


# LB4-G/M4

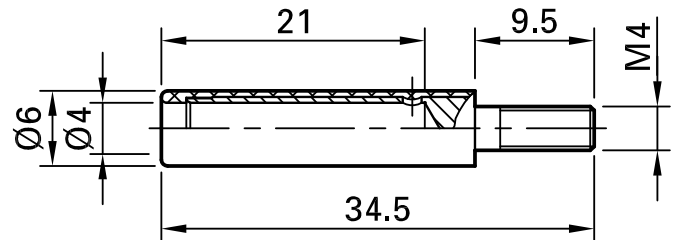

Item number 23.0280-\*

Insulated, with external thread for screw connection to threaded holes. Machined brass. Ø 4 mm rigid socket in insulator accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve.

Technical data	
Diameter of plug system	4 mm
Rated Values	600 V, CAT II, 32 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	21 22
Optional color(s)	23 24
Thread	M4
Test accessory acc. to	IEC EN 61010-031
User-Information	I 119