


# LK1-A

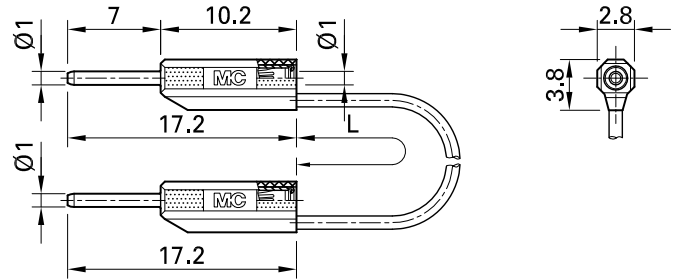

Item number 28.0026-\*

Highly flexible, with stackable Ø 1 mm rigid plugs on both ends.

Technical data	
Diameter of plug system	1 mm
Rated Values	30 V, 3 A / 60 V, 3 A
Surface treatment electrical contact	Au
Base material electrical contact	CuZn
Standard color(s) *	<span style="background-color: black; color: white; padding: 2px;">21</span> <span style="background-color: red; color: white; padding: 2px;">22</span>
Optional color(s)	<span style="background-color: blue; color: white; padding: 2px;">23</span>
Lead lengths <input type="text"/>	015; 030 cm
Lead insulation	PVC
Lead cross section	0,127 mm <sup>2</sup>
Test accessory acc. to	IEC EN 61010-031