


SAB4-G/N-X

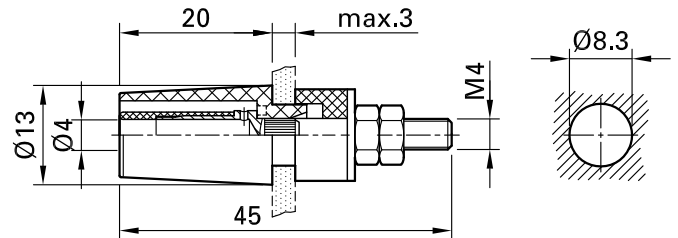

Item number 49.7042-*

Insulated, rigid, Ø 4 mm, accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve. Machined brass. The socket is surface-mounted in pre-drilled panels of plastic, metal, etc. Threaded bolt M4.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT II, 32 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	20 21 22 23 24 25 26 27 28 29
Thread	M4
Test accessory acc. to	IEC EN 61010-2-030
Supplied assembly material	2x MU0,8D/M4N; U/4,3x12; ID-SAB4-G
Remarks	Accessories: Tube spanner SS2
Approvals	UR