


# BL2-12/20/A

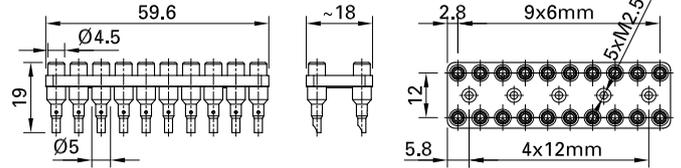

Item number 63.9358-\*

20-pole socket strips, consisting of 2 rows of 10 rigid sockets with solder connection. No need for individual mounting of sockets. Simplified panel drilling, orientation of solder connections and compact mounting with only 5 screws. Socket spacing of 12 mm.

Technical data	
Diameter of plug system	2 mm
Rated Values	30 V, 10 A / 60 V, 10 A
Surface treatment electrical contact	Au
Base material electrical contact	CuZn
Standard color(s) *	21 22 23 24 25
Optional color(s)	29
Test accessory acc. to	IEC EN 61010-2-030