


AF-4A2A-F05

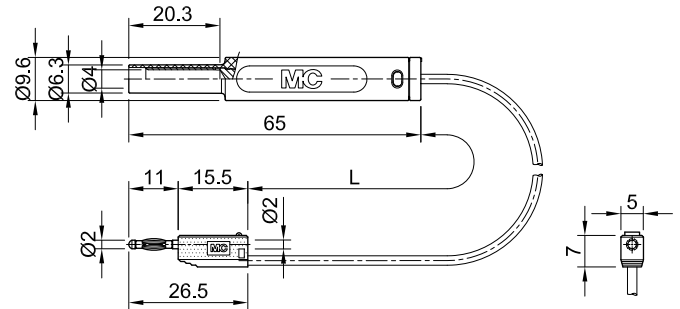

Item number 64.1073-*

Highly flexible. One end with Ø 2 mm stackable MULTILAM plug, the other end with Ø 4 mm rigid socket with rigid insulating sleeve.

Technical data	
Diameter of plug system	4 mm / 2 mm
Rated Values	30 V, 10 A / 60 V, 10 A
Surface treatment electrical contact	Au
Base material electrical contact	CuZn
Standard color(s) *	21 22
Lead lengths <input type="text"/>	015 cm
Lead insulation	PVC
Lead cross section	0,5 mm ²
Test accessory acc. to	IEC EN 61010-031
User-Information	I 093