


SLK-4N-S25

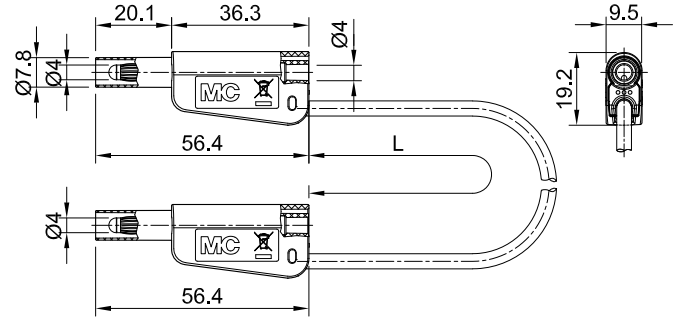

Item number 66.2016-*

Highly flexible, with stackable Ø 4 mm MULTILAM plugs with rigid insulating sleeve on both ends.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT II, 32 A / 600 V, CAT III, 32 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	<input type="checkbox"/> 20 <input type="checkbox"/> 21 <input type="checkbox"/> 22 <input type="checkbox"/> 23 <input type="checkbox"/> 24 <input type="checkbox"/> 25 <input type="checkbox"/> 26 <input type="checkbox"/> 27 <input type="checkbox"/> 28 <input type="checkbox"/> 29 <input type="checkbox"/> 30
Lead lengths <input type="text"/>	025; 050; 075; 100; 150; 200 cm
Lead insulation	SIL
Lead cross section	2,5 mm ²
Test accessory acc. to	IEC EN 61010-031
Approvals	UL, CE