


# SLQ-4N-39

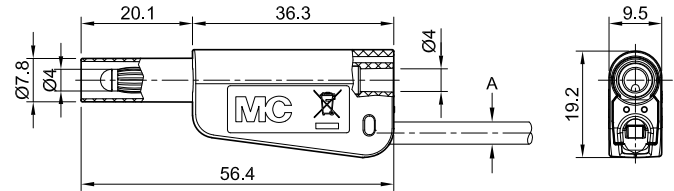

Item number 66.2018-\*

Stackable, Ø 4 mm, with spring-loaded MULTILAM, for self-assembly of test leads. With rigid insulating sleeve. Solder connection.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT II, 19 A / 600 V, CAT III, 19 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	<span style="background-color: #ffff00; border: 1px solid black; padding: 2px;">20</span> <span style="background-color: #000000; color: white; border: 1px solid black; padding: 2px;">21</span> <span style="background-color: #ff0000; color: white; border: 1px solid black; padding: 2px;">22</span> <span style="background-color: #0000ff; color: white; border: 1px solid black; padding: 2px;">23</span> <span style="background-color: #ffff00; border: 1px solid black; padding: 2px;">24</span> <span style="background-color: #008000; color: white; border: 1px solid black; padding: 2px;">25</span> <span style="background-color: #800080; color: white; border: 1px solid black; padding: 2px;">26</span> <span style="background-color: #a52a2a; color: white; border: 1px solid black; padding: 2px;">27</span> <span style="background-color: #808080; color: white; border: 1px solid black; padding: 2px;">28</span> <span style="background-color: #d3d3d3; color: white; border: 1px solid black; padding: 2px;">29</span> <span style="background-color: #ff4500; color: white; border: 1px solid black; padding: 2px;">30</span>
Outer diameter	3.9 mm
Test accessory acc. to	IEC EN 61010-031
Component parts	KT-SL-4-39; LS-SLQ-4N
Approvals	UR