


# SBL-4N-39

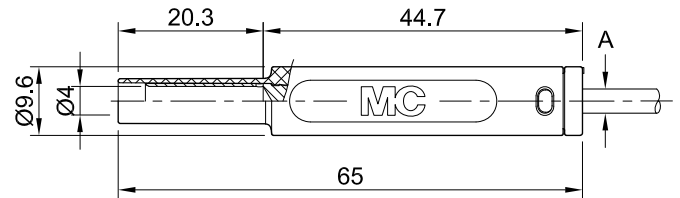

Item number 66.2050-\*

In-line, rigid, Ø 4 mm, accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve, for self-assembly of test leads. Solder connection.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT II, 32 A / 600 V, CAT III, 32 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	21 22 23 24 25 29
Optional color(s)	20 26 27 28
Test accessory acc. to	IEC EN 61010-031
Approvals	UR