


XHM-5000

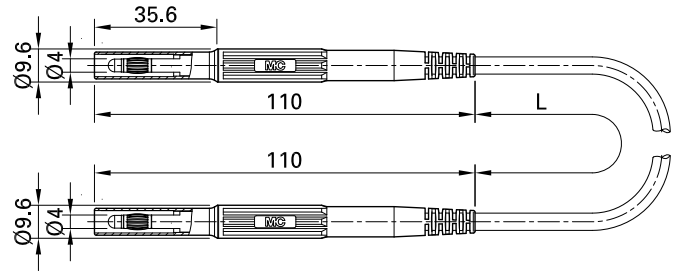

Item number 66.9425- *

Highly flexible, with in-line Ø 4 mm MULTILAM plug with rigid insulating sleeve on both ends.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT IV, 10 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	21 22 23
Lead lengths <input type="text"/>	150 cm
Lead insulation	TPE
Lead cross section	0,5 mm ²
Test accessory acc. to	IEC EN 61010-031
User-Information	I 079
Remarks	Rated voltage 5'000 V: Output voltage of test instruments, e.g. insulation testers
Approvals	CE