
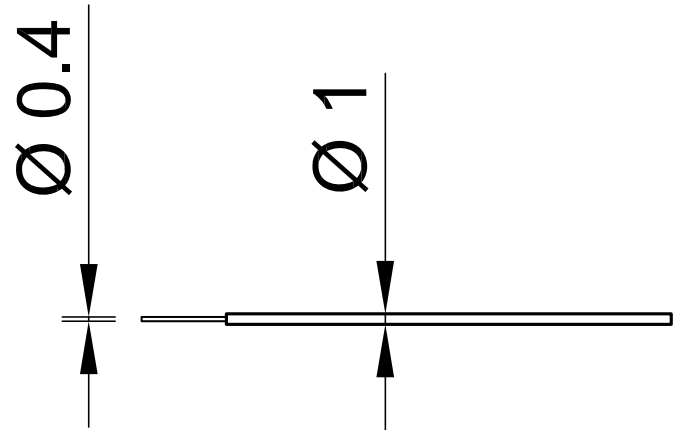


FLEXI-E 0,10

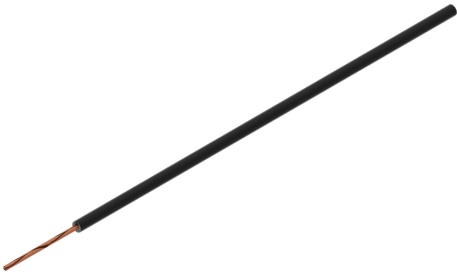

Item number 60.7001-*

Highly flexible basic insulated stranded wire 0,10 mm².

Technical data	
Rated Values	AC 150 V, 2 A
Standard color(s) *	21 22 23 25 29
Lead insulation	PVC
Temperature range	-10 °C ... +70 °C
Strand design (n x Ø mm)	26x0,07
Lead weighth	1.8 kg/km
Conductor diameter	0.4 mm
Cable diameter	1.0 mm
Insulation thickness	0.3 mm
Approvals	CE, UKCA, EAC