
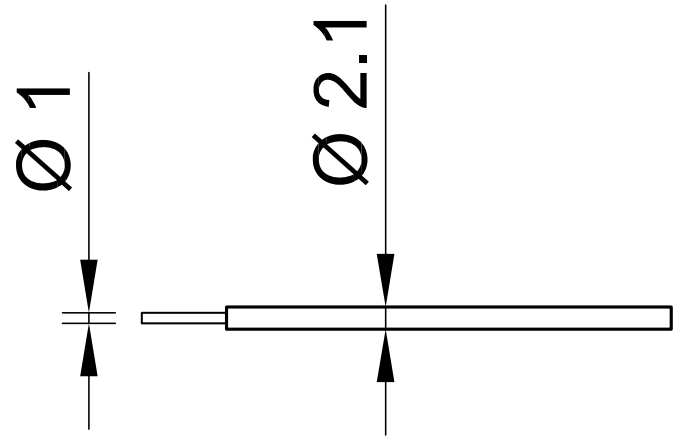


FLEXI-E/HK 0,50

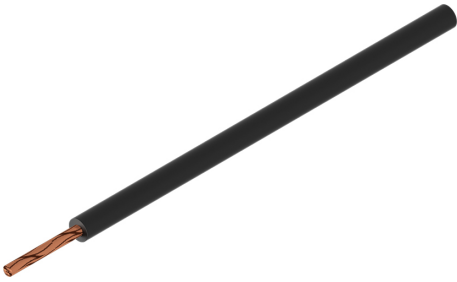

Item number 60.7005-*

Highly flexible basic insulated stranded wire 0,50 mm².

Technical data	
Rated Values	AC 500 V, 10 A
Standard color(s) *	21 22 23 24 25 29
Lead insulation	PVC
Temperature range	-10 °C ... +70 °C
Strand design (n x Ø mm)	256 x 0,05
Lead weighth	8.3 kg/km
Conductor diameter	1.0 mm
Cable diameter	2.1 mm
Insulation thickness	0.55 mm
Approvals	CE, UKCA, EAC