


FLEXI-S 4,0

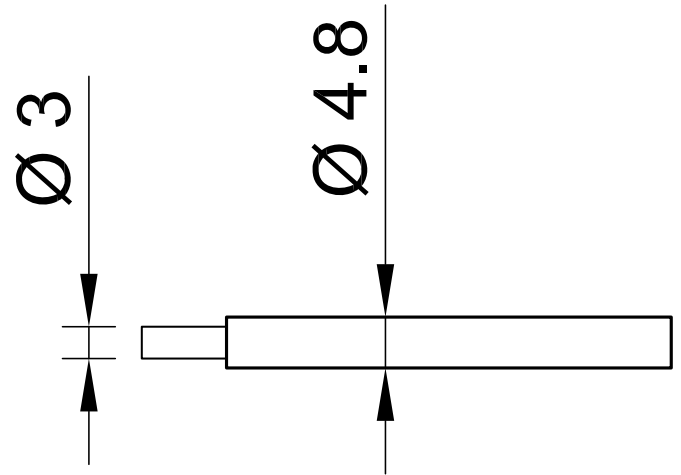

Item number 60.7014-*

Highly flexible stranded wire 4,0 mm² with reinforced insulation .

Technical data	
Rated Values	AC 1000 V, 42 A / DC 1500 V, 42 A
Standard color(s) *	20 21 22 23 33
Lead insulation	PVC
Temperature range	-10 °C ... +70 °C
Strand design (n x Ø mm)	1036 x 0,07
Lead weight	52.0 kg/km
Conductor diameter	3.0 mm
Cable diameter	4.8 mm
Insulation thickness	0.9 mm
Approvals	UR, CE, UKCA, EAC