
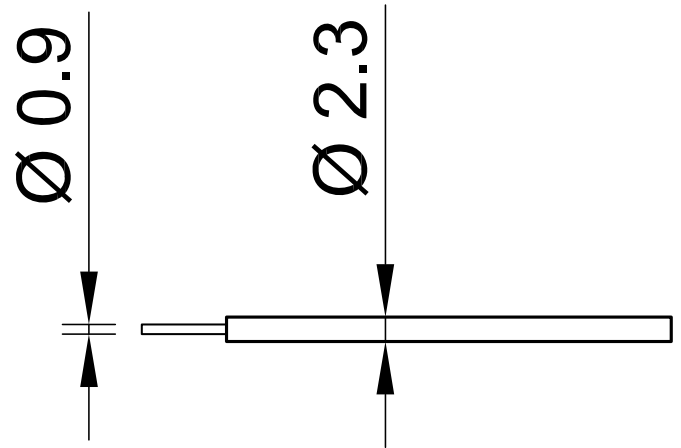


FLEXI-2V 0,50

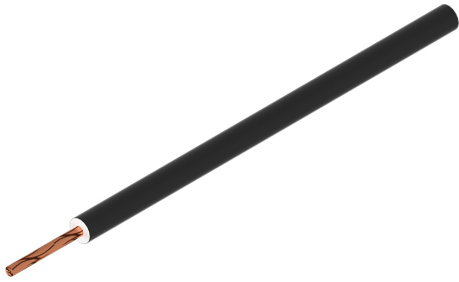

Item number 60.7027-*

Highly flexible stranded wire 0,50 mm² with reinforced, double-layer insulation for the highest safety

Technical data	
Rated Values	AC 1000 V, 10 A / DC 1500 V, 10 A
Standard color(s) *	21 22 23
Lead insulation	PVC
Temperature range	-10 °C ... +70 °C
Strand design (n x Ø mm)	129 x 0,07
Lead weight	9.2 kg/km
Conductor diameter	0.9 mm
Cable diameter	2.3 mm
Insulation thickness	0.72 mm
Approvals	UR, CE, UKCA, EAC