


# FLEXI-2V 2,5

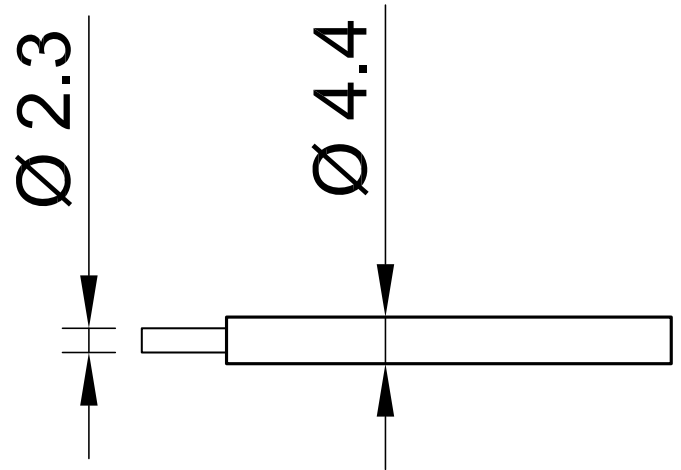

Item number 60.7032-\*

Highly flexible stranded wire 2,5 mm<sup>2</sup> with reinforced, double-layer insulation for the highest safety

Technical data	
Rated Values	AC 1000 V, 32 A / DC 1500 V, 32 A
Standard color(s) *	<span style="background-color: black; color: white; padding: 2px;">21</span> <span style="background-color: red; color: white; padding: 2px;">22</span> <span style="background-color: blue; color: white; padding: 2px;">23</span> <span style="background-color: yellow; color: black; padding: 2px;">24</span> <span style="background-color: green; color: white; padding: 2px;">25</span> <span style="background-color: purple; color: white; padding: 2px;">26</span>
Lead insulation	PVC
Temperature range	-10 °C ... +70 °C
Strand design (n x Ø mm)	651 x 0,07
Lead weight	38.0 kg/km
Conductor diameter	2.3 mm
Cable diameter	4.4 mm
Insulation thickness	1.0 mm
Approvals	UR, CE, UKCA, EAC