


# FLEXI-HV 0,75

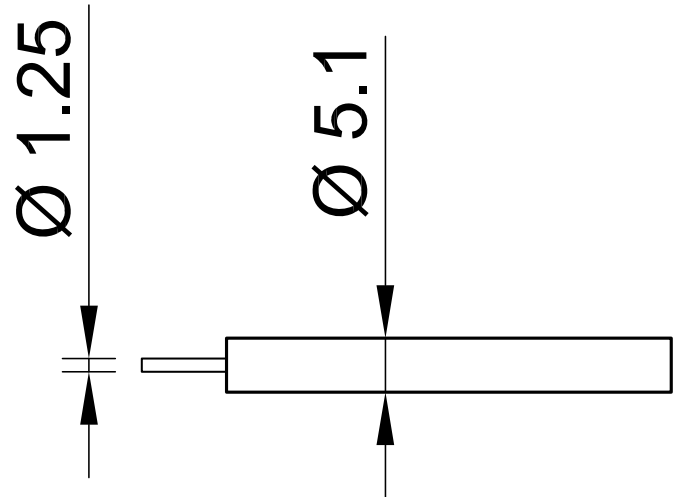

Item number 60.7067-\*

Highly flexible, reinforced insulated stranded wires 0,75 mm<sup>2</sup>.

Technical data	
Rated Values	AC 10000 V, 15 A
Standard color(s) *	<span style="background-color: red; color: white; padding: 2px;">22</span>
Lead insulation	PVC
Temperature range	-10 °C ... +70 °C
Strand design (n x Ø mm)	196 x 0,07
Lead weighth	33.0 kg/km
Conductor diameter	1.25 mm
Cable diameter	5.1 mm
Insulation thickness	1.9 mm