


# FLEXI-1V 0,75

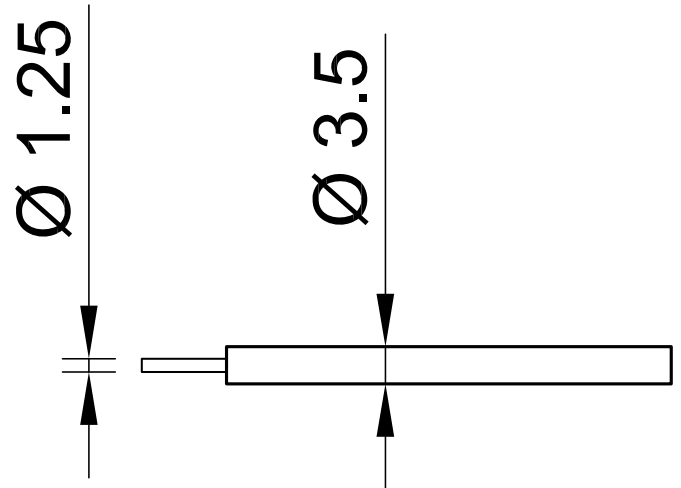

Item number 60.7086-\*

Highly flexible stranded wire 0,75 mm<sup>2</sup> with reinforced insulation.

Technical data	
Rated Values	AC 1000 V, 15 A / DC 1500 V, 15 A
Standard color(s) *	20 21 22 29
Lead insulation	PVC
Temperature range	-10 °C ... +70 °C
Strand design (n x Ø mm)	196 x 0,07
Lead weight	18.0 kg/km
Conductor diameter	1.25 mm
Cable diameter	3.5 mm
Insulation thickness	1.1 mm
Approvals	UR, CE, UKCA, EAC