
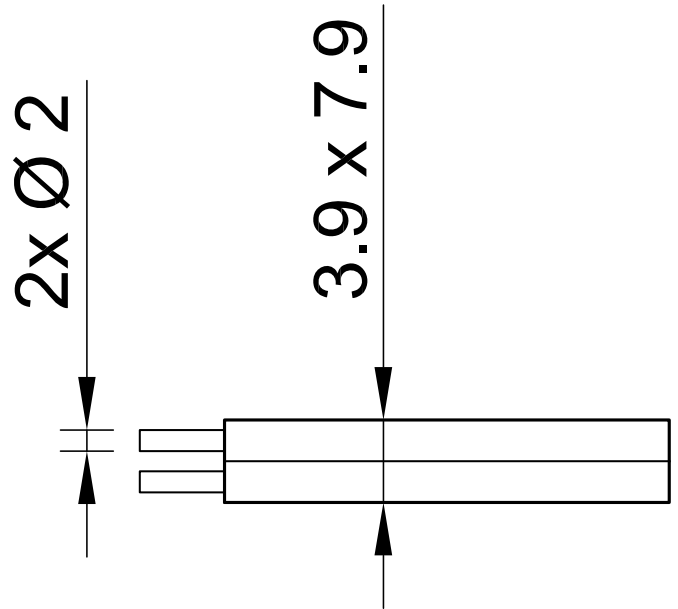


FLEXI-ZW 2,0

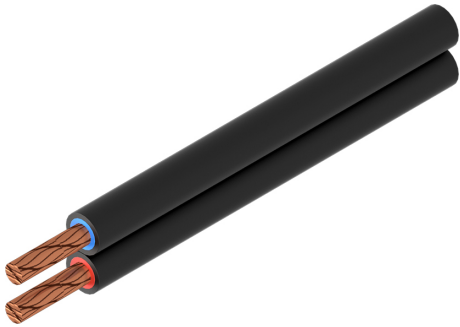

Item number 60.7456-*

Twin wires with single insulated wires 2,0 mm² in a black jacket.

Technical data	
Rated Values	AC 1000 V, 24 A / DC 1500 V, 24 A
Standard color(s) *	21
Lead insulation	PVC
Temperature range	-10 °C ... +70 °C
Strand design (n x Ø mm)	525 x 0,07
Lead weight	62.0 kg/km
Conductor diameter	2.0 mm
Cable diameter	3.9 mm
Insulation thickness	0.95 mm
Approvals	CE, UKCA, EAC