


PLAST-HV 0,5 SN

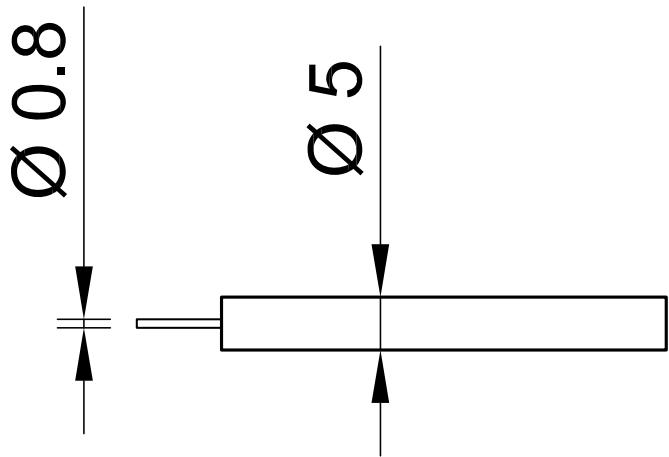

Item number 60.7460-*

Highly flexible, reinforced insulated stranded wires 0,5 mm² (tin plated).

Technical data	
Rated Values	AC 5000 V, 10 A
Standard color(s) *	21 22 23
Lead insulation	TPE
Temperature range	-30 °C ... +105 °C
Strand design (n x Ø mm)	129 x 0,07
Lead weigth	26.0 kg/km
Conductor diameter	0.8 mm
Cable diameter	5.0 mm
Insulation thickness	2.1 mm
Approvals	UR