


SILI-S 10

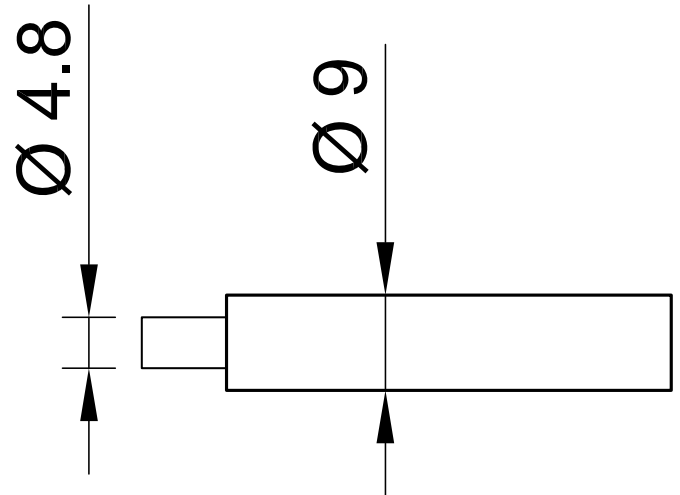

Item number 61.7613-*

Highly flexible stranded wire 10 mm² with reinforced insulation.

Technical data	
Rated Values	AC 1000 V, 75 A / DC 1500 V, 75 A
Standard color(s) *	21 22 23 33
Lead insulation	SIL
Temperature range	-50 °C ... +90 °C
Strand design (n x Ø mm)	2556 x 0,07
Lead weight	145.0 kg/km
Conductor diameter	4.8 mm
Cable diameter	9.0 mm
Insulation thickness	2.1 mm
Approvals	UR, CE, UKCA, EAC