
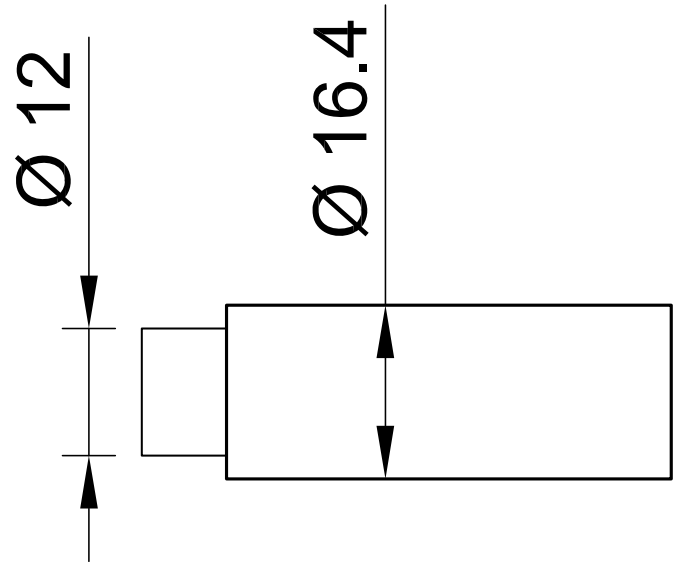


SILI-S 70

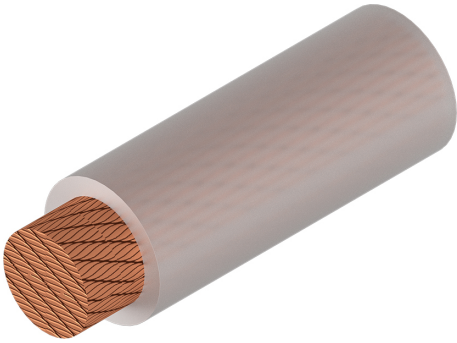

Item number 61.7618-*

Highly flexible stranded wire 70 mm² with reinforced insulation.

Technical data	
Rated Values	AC 1000 V, 245 A / DC 1500 V, 245 A
Standard color(s) *	33
Lead insulation	SIL
Temperature range	-50 °C ... +90 °C
Strand design (n x Ø mm)	8967 x 0,10
Lead weight	760.0 kg/km
Conductor diameter	12.0 mm
Cable diameter	16.4 mm
Insulation thickness	2.2 mm
Approvals	CE, UKCA, EAC