


SILI-HV 0,5

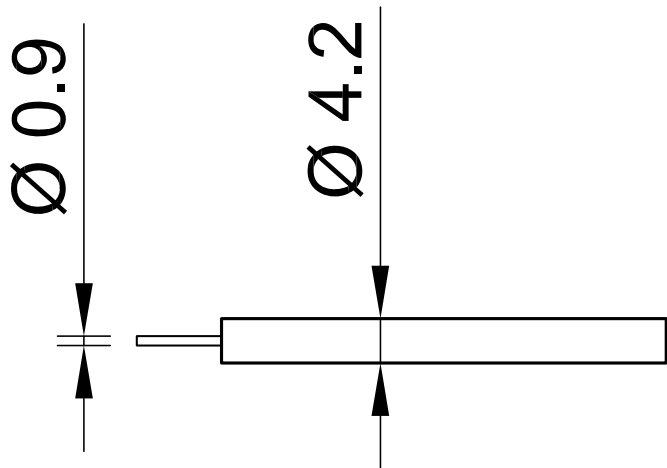

Item number 61.7630-*

Super flexible, reinforced insulated stranded wire 0,50 mm².

Technical data	
Rated Values	AC 5000 V, 10 A
Standard color(s) *	21 22
Lead insulation	SIL
Temperature range	-50 °C ... +90 °C
Strand design (n x Ø mm)	129 x 0,07
Lead weighth	20.0 kg/km
Conductor diameter	0.9 mm
Cable diameter	4.2 mm
Insulation thickness	1.65 mm