


SILI-HV 0,75

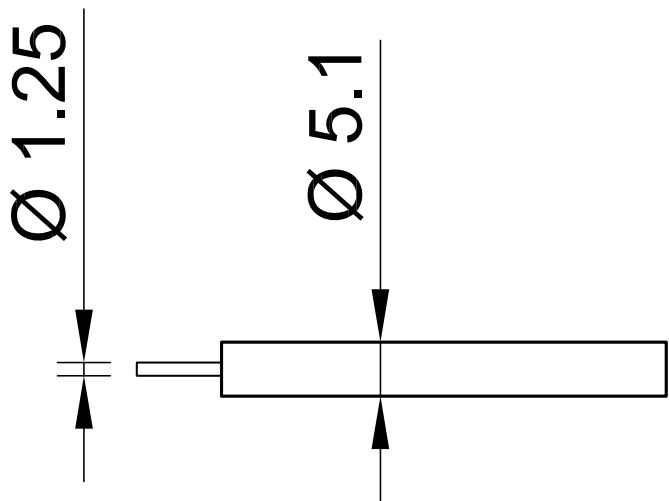

Item number 61.7631-*

Super flexible, reinforced insulated stranded wire 0,75 mm².

Technical data	
Rated Values	AC 7500 V, 15 A
Standard color(s) *	21 22
Lead insulation	SIL
Temperature range	-50 °C ... +90 °C
Strand design (n x Ø mm)	196 x 0,07
Lead weighth	29.0 kg/km
Conductor diameter	1.25 mm
Cable diameter	5.1 mm
Insulation thickness	1.9 mm