


SILI-HV 6,0

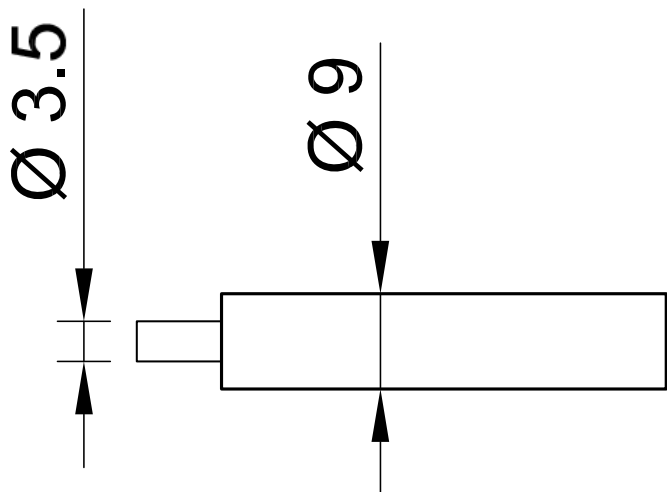

Item number 61.7636-*

Super flexible, reinforced insulated stranded wire 6,0 mm².

Technical data	
Rated Values	AC 20000 V, 54 A
Standard color(s) *	22
Lead insulation	SIL
Temperature range	-50 °C ... +90 °C
Strand design (n x Ø mm)	1548 x 0,07
Lead weigth	120.0 kg/km
Conductor diameter	3.5 mm
Cable diameter	9.0 mm
Insulation thickness	2.75 mm