


SILI-HV 2,5/9

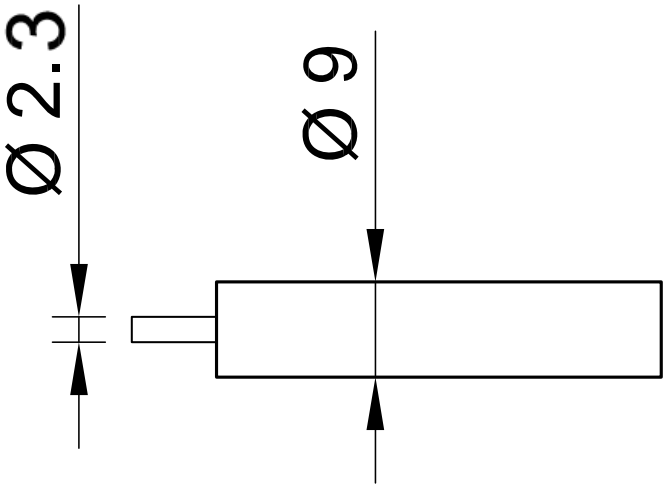

Item number 61.7639-*

Super flexible, reinforced insulated stranded wire 2,5 mm².

Technical data	
Rated Values	AC 30000 V, 32 A
Standard color(s) *	22
Lead insulation	SIL
Temperature range	-50 °C ... +90 °C
Strand design (n x Ø mm)	651 x 0,07
Lead weighth	93.0 kg/km
Conductor diameter	2.3 mm
Cable diameter	9.0 mm
Insulation thickness	3.35 mm