


# XLAM-SLK-4N-RG58

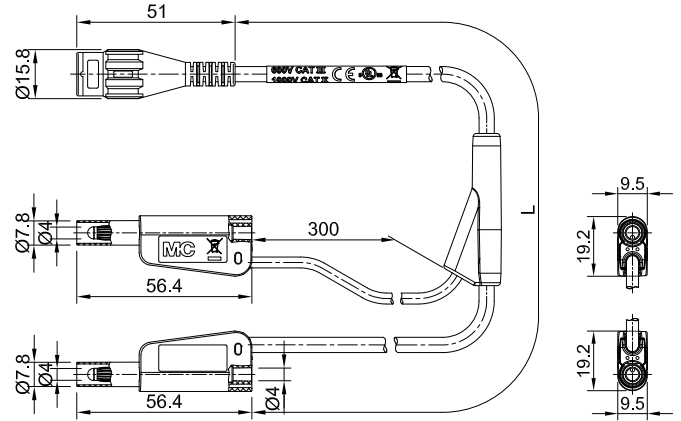


Item number 66.1030-

Highly flexible, fully shielded adapter leads. One end with coaxial cable with touch-protected BNC male connector, other end with stackable Ø 4 mm MULTILAM plugs with rigid insulating sleeve.

Technical data	
Diameter of plug system	4 mm / BNC
Rated Values	1000 V, CAT II / 600 V, CAT III
Surface treatment electrical contact	Ni; Au
Base material electrical contact	CuZn
Lead lengths <input type="text"/>	100; 160 cm
Lead insulation	PVC
Temperature range	-10°C ... +70°C
Test accessory acc. to	IEC EN 61010-031
Cable lengths options	100; 160 cm
Approvals	UL, CE

# XLAM-SLK-4N-SILI-SC05

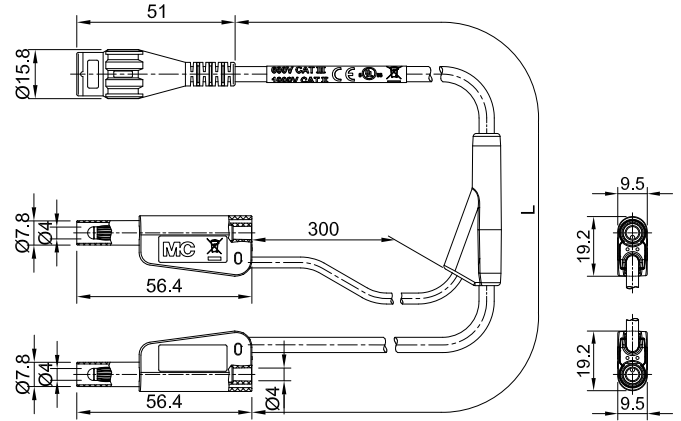

Item number 66.1031-

Highly flexible, fully shielded adapter leads. One end with coaxial cable with touch-protected BNC male connector, other end with stackable Ø 4 mm MULTILAM plugs with rigid insulating sleeve.

Technical data	
Diameter of plug system	4 mm / BNC
Rated Values	1000 V, CAT II / 600 V, CAT III
Surface treatment electrical contact	Ni; Au
Base material electrical contact	CuZn
Lead lengths <input type="text"/>	100; 160 cm
Lead insulation	SIL
Temperature range	-10°C ... +70°C
Test accessory acc. to	IEC EN 61010-031
Approvals	UL, CE