


XLAM-SAK-4N-RG58

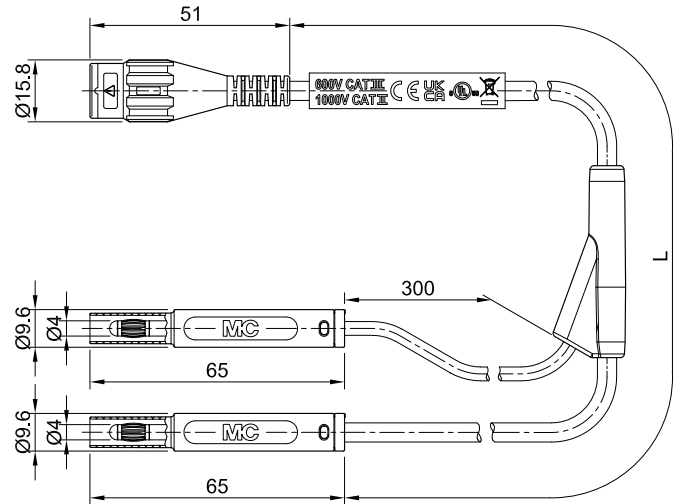


Data sheet XLAM-SAK-4N-RG58 08.2024

Item number 66.1051-

Highly flexible, fully shielded adapter leads. One end with coaxial cable with touch-protected BNC male connector, other end with in-line Ø 4 mm MULTILAM plugs with rigid insulating sleeve.

Technical data	
Diameter of plug system	4 mm / BNC
Rated Values	1000 V, CAT II / 600 V, CAT III
Surface treatment electrical contact	Ni; Au
Base material electrical contact	CuZn
Lead lengths <input type="text"/>	100; 160 cm
Lead insulation	PVC
Temperature range	-10°C ... +70°C
Test accessory acc. to	IEC EN 61010-031
User-Information	I 014
Approvals	UL, CE

XLAM-SAK-4N-SILI-SC05

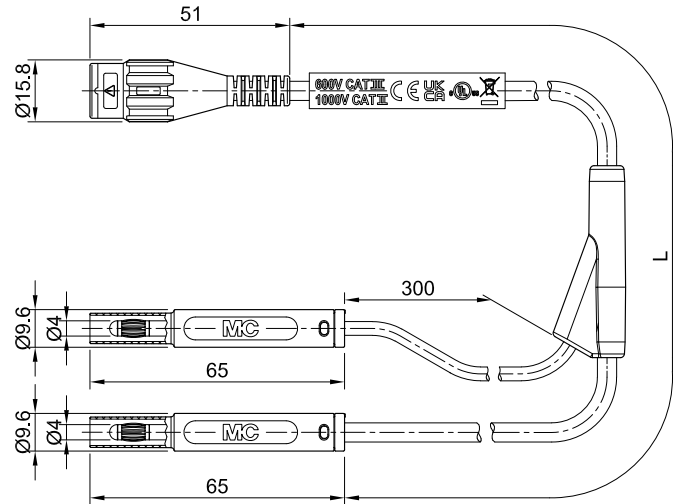

Data sheet XLAM-SAK-4N-SILI-SC05 12.2024

Item number 66.1052-

Highly flexible, fully shielded adapter leads. One end with coaxial cable with touch-protected BNC male connector, other end with in-line Ø 4 mm MULTILAM plugs with rigid insulating sleeve.

Technical data	
Diameter of plug system	4 mm / BNC
Rated Values	1000 V, CAT II / 600 V, CAT III
Surface treatment electrical contact	Ni; Au
Base material electrical contact	CuZn
Lead lengths <input type="text"/>	100; 160 cm
Lead insulation	SIL
Temperature range	-50°C ... +70°C
Test accessory acc. to	IEC EN 61010-031
User-Information	I 014
Approvals	UL, CE