


B4-E-M3-I

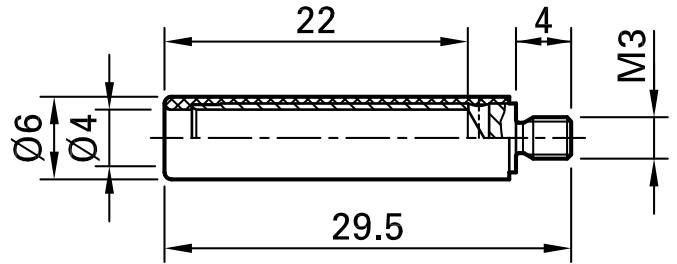


Item number 23.1031-*

Insulated, with external thread for screw connection to threaded holes. Machined brass. Ø 4 mm rigid socket in insulator accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve. Socket with internal slot for screwdriver.

Technical data	
Diameter of plug system	4 mm
Rated Values	600 V, CAT II, 32 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	21 22 23 24
Thread	M3
Test accessory acc. to	IEC EN 61010-031
User-Information	I 119

B4-E-M4-I

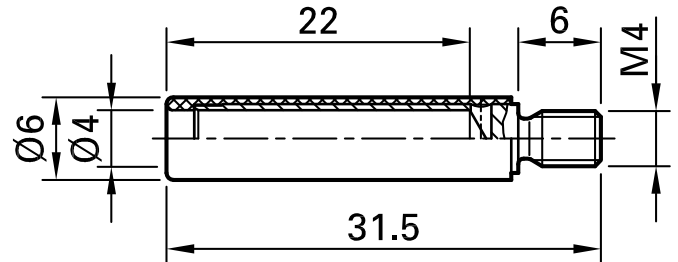

Item number 23.1033-*

Insulated, with external thread for screw connection to threaded holes. Machined brass. \varnothing 4 mm rigid socket in insulator accepting spring-loaded \varnothing 4 mm plugs with rigid insulating sleeve. Socket with internal slot for screwdriver.

Technical data	
Diameter of plug system	4 mm
Rated Values	600 V, CAT II, 32 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	21 22 23 24
Thread	M4
Test accessory acc. to	IEC EN 61010-031
User-Information	I 119